 



Ball valve actuator unit VZPR-BPD-22-R4R

Part number: 550337

FESTO

Comprising pneumatic DAPS semi-rotary actuator, combined with a 2/2-way VAPB ball valve in stainless steel version.

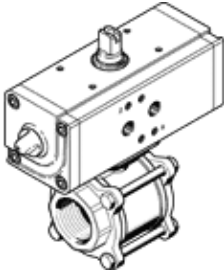

Data sheet

Feature	Value
Design structure	2-way ball valve Swivel actuator
Type of actuation	electrical pneumatic
Assembly position	Any
Mounting type	Line installation
Process valve connection	Rp4
Switching position indicator	Slot direction = flow direction
Nominal diameter DN	100
Working pressure	6 ... 8.4 bar
Working pressure, ball valve actuator	1 ... 8.4 bar
Nominal pressure of process valve	63
Medium	Compressed air in accordance with ISO8573-1:2010 [-:--:] Inert gases Water Neutral fluids
Medium temperature	-10 ... 200 °C
Ambient temperature	-20 ... 80 °C
Materials note	Contains PWIS substances
Food-industry approval	No
Product weight	26,500 g
Corrosion resistance classification CRC	3