


Plug socket with cable KMYZ-4-2,5-B-EX

Part number: 550481

FESTO

Combination of MSZB and MSZC connection.

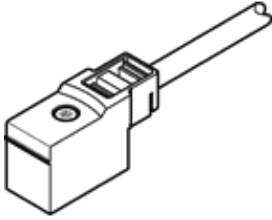

Data sheet

Feature	Value
Maritime classification	see certificate
Mounting type	On solenoid valve with M2 central screw
Assembly position	Any
Product weight	34.5 g
Electrical connection	Plug socket angled Cable Rectangular design, MSZB
Operating voltage range DC	3 ... 36 V
Nominal operating voltage DC	24 V
Acceptable current load at 40°C	1 A
Surge strength	900 V
Protective earth connection	Not available
Cable length	2.5 m
Cable attribute	Standard
Cable structure	2x0,35
Protection class	IP40
Ambient temperature	-10 ... 50 °C
CE symbol (see declaration of conformity)	in accordance with EU RoHS directive
UKCA marking (see declaration of conformity)	To UK RoHS instructions
PWIS conformity	VDMA24364-B2-L
Materials note	Conforms to RoHS
Corrosion resistance classification CRC	1 - Low corrosion stress
Material cable sheath	PVC
Material housing	PA
Material electrical contact	Bronze