


Coupling

EAMC-65-90-19-25

Part number: 551000

FESTO

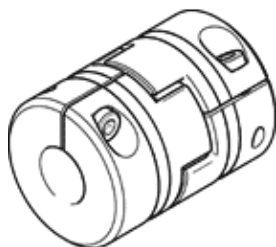

Data sheet

Feature	Value
Holder diameter 1	19 mm
Holder diameter 2	25 mm
Size	65
Nominal length	90 mm
Assembly position	Any
Max. speed	4,500 1/min
Storage temperature	-25 ... 60 °C
Relative air humidity	0 - 95 %
Ambient temperature	-25 ... 60 °C
Mass moment of inertia	417 kgmm ²
Transferable torque	85 Nm
Product weight	535 g
Materials note	Conforms to RoHS