


Fiber-optic cable SOOC-DS-M-A11-2-R25

Part number: 552810

FESTO

Suitable for SOE4 fiber-optic units.

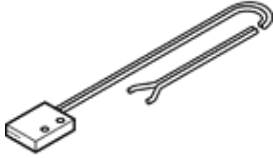

Data sheet

Feature	Value
Materials note	Contains PWIS substances
Measurement method	Diffuse reflection sensor
Minimal object diameter	0.15 mm
Fiber-optic cable - special feature	Series
Working range	130 mm
Ambient temperature	-55 ... 70 °C
Size, head	Rectangle 19x25x6 mm
Fiber optic cable length	2 m
Min. bending radius	25 mm
Outside diameter	2.2 mm
Material housing	Brass Nickel plated
Material fibre-optic	PE
Protection class	IP66
Corrosion resistance classification CRC	1 - Low corrosion stress