


Bellows kit DADB-V6-80-S51-125

Part number: 553353

FESTO

For standard cylinders to ISO 15552

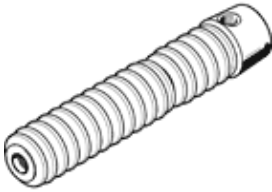

Data sheet

Feature	Value
Outside diameter	93 mm
Size	80
Stroke range	51 ... 125 mm
Piston rod extension	37 mm
Design	Round
Assembly position	Any
Design structure	Bellows kit with ducted exhaust air
Corrosion resistance classification CRC	3 - High corrosion stress
PWIS conformity	VDMA24364-B2-L
Resistance to media	Dust Chippings Oils Grease Gasolines
Protection class	IP54
Ambient temperature	-10 ... 80 °C
Product weight	127 g
Mounting type	slip-on With threaded pin
Pneumatic connection	G1/4
Materials note	Conforms to RoHS
Material adapter components	PA-reinforced
Material seals	NBR
Material bellows	NBR
Material threaded pin	High alloy steel, non-corrosive