


Connecting cable NEBV-H1G2L-P-2.5-LE2

Part number: 554031

FESTO

für Magnetventile MH1, ohne LED.

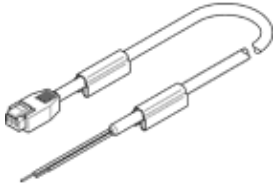

Data sheet

Feature	Value
Assembly position	Any
Cable attribute	Für statische Anwendungen
Polarity protected	No
Operating status display	Yellow LED
Operating voltage range AC	4.5 ... 26.4 V
Operating voltage range DC	4.5 ... 26.4 V
maximum output current	2,000 mA
Stoßspannungsfestigkeit	0.8 kV
Corrosion resistance classification CRC	4
Protection class	IP40
Ambient temperature	-5 ... 70 °C -20 ... 70 °C
Product weight	60 g
Electrical connection	2-core Straight socket / cable
Cable length	2.5 m
Mounting type	Clip
Color code, core insulation	Pin 1 = black Pin 3 = schwarz/rot
Materials note	Free of copper and PTFE
Materials information, housing	POM PUR
Materials information, cable sheaths	PVC