 



# Distributor block MS6N-FRM-FRZ

Part number: 554102

FESTO

Appropriate as adapter between twop pressure regulator.

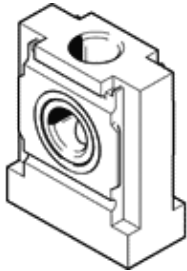

## Data sheet

Feature	Value
Assembly position	Any
Design structure	Branching module
Working pressure	0 ... 20 bar
Standard nominal flow rate in main flow direction 1->2	14,600 l/min
Standard nominal flow rate outlet at top	10,400 l/min
Standard nominal flow rate outlet at bottom	9,850 l/min
Authorization	c UL us - Recognized (OL)
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:4:4] Inert gases
Note on operating and pilot medium	Lubricated operation possible (subsequently required for further operation)
Corrosion resistance classification CRC	2 - Moderate corrosion stress
PWIS conformity	VDMA24364-B2-L
Storage temperature	-10 ... 60 °C
Medium temperature	-10 ... 60 °C
Ambient temperature	-10 ... 60 °C
Product weight	163 g
Pneumatic connection, port 3	NPT1/2-14
Pneumatic connection, port 4	NPT1/2-14
Materials note	Conforms to RoHS
Material housing	Aluminum die cast