


# Angled connector plate

## VABF-S2-2-A1G2-N12

Part number: 555703

FESTO

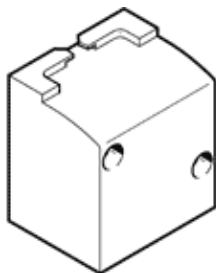

### Data sheet

Feature	Value
Width	58.1 mm
Based on the standard	ISO 5599-2
Assembly position	Any
Operating pressure MPa	-0.09 ... 1 MPa
Working pressure	-0.9 ... 10 bar
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:4:4]
Note on operating and pilot medium	Lubricated operation possible (subsequently required for further operation)
Corrosion resistance classification CRC	0 - No corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Protection class	IP65 NEMA 4
Ambient temperature	-5 ... 50 °C
Product weight	359 g
Mounting type	with through hole
Materials note	Conforms to RoHS
Material housing	Wrought Aluminum alloy