


Encoder cable NEBM-T1G12-T1G12-5

Part number: 556797

FESTO

For connecting the motor and controller

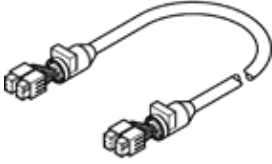

Data sheet

Feature	Value
Cable attribute	Suitable for chain link trunking
Degree of contamination	3
Protection class	in assembled condition IP65
Ambient temperature with flexible cable installation	-40 ... 90 °C
Ambient temperature	-50 ... 90 °C
Min. cable bending radius	82 mm
Cable structure	Shielded 5 x (2 x 0,34 mm ²) + 2 x 0,5mm ²
Cable diameter	11 mm
Cable length	5 m
Materials note	Contains PWIS substances Conforms to RoHS
Materials information, cable sheaths	TPE-U(PUR)