


Manifold strip MHJ10-P16

Part number: 557608

FESTO

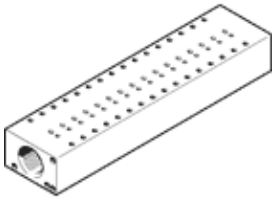

Data sheet

Feature	Value
Grid dimension	11 mm
Polarity protected	for operating voltage
Max. number of valve positions	16 Versions to customer requirements possible
Authorization	RCM Mark
Corrosion resistance classification CRC	2 - Moderate corrosion stress
PWIS conformity	VDMA24364-B2-L
Product weight	635 g
Mounting type	With mounting bracket
Pneumatic connection, port 1	G1/2
Pneumatic connection, port 2	M7
Materials note	Conforms to RoHS
Material manifold	Anodised wrought aluminium alloy