

Manifold strip


VABM-C8-12E-G14-28-M1

Part number: 557677

Classic - do not use for new projects

[Modern alternatives can be found by entering the first four characters of the type code in the search field.](#)

FESTO

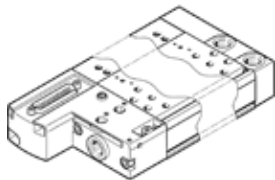

Data sheet

Feature	Value
Grid dimension	12 mm
Max. number of valve positions	28
Corrosion resistance classification CRC	0 - No corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Max. tightening torque, valve mounting	0.6 Nm
Max. tightening torque, wall mounting	5 Nm
Product weight	1,704 g
Pneumatic connection, port 1	G1/4
Pneumatic connection, port 3	G1/4
Pneumatic connection, port 5	G1/4
Materials note	Conforms to RoHS
Material manifold	Wrought Aluminum alloy