


Drive shaft EAMB-34-6-25X26-23X27

Part number: 558037

FESTO

for adapting drives with hollow shaft

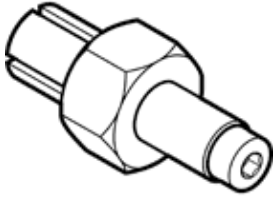

Data sheet

Feature	Value
Holder diameter 1	25 mm
Holder diameter 2	23 mm
Size	120
Nominal length	26 mm
Assembly position	Any
Max. speed	5,500 1/min
PWIS conformity	VDMA24364-B2-L
Storage temperature	-25 ... 60 °C
Relative air humidity	0 - 95 %
Ambient temperature	-25 ... 60 °C
Mass moment of inertia	18.2 kgmm ²
Transferable torque	100 Nm
Product weight	201 g
Materials note	Conforms to RoHS