


# Coupling EAMC-20-30-5-6

Part number: 558902

FESTO

Suitable for cantilever axis EGSA.

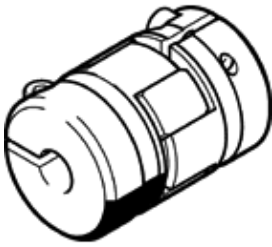

## Data sheet

Feature	Value
Holder diameter 1	5 mm
Holder diameter 2	6 mm
Size	20
Nominal length	30 mm
Assembly position	Any
Max. speed	9,000 1/min
PWIS conformity	VDMA24364-B2-L
Storage temperature	-25 ... 60 °C
Relative air humidity	0 - 95 %
Ambient temperature	-25 ... 60 °C
Mass moment of inertia	1.06 kgmm <sup>2</sup>
Transferable torque	2.2 Nm
Product weight	20 g
Materials note	Conforms to RoHS