


Controller FED-CEC

Part number: 559869
Product to be discontinued

FESTO

for controlling electric drive units with front end display.
Type to be discontinued. Available until 2017. See Support Portal for alternative products.

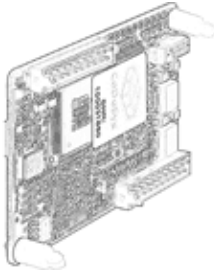

Data sheet

Feature	Value
CE symbol (see declaration of conformity)	according to EU-EMV guideline
Storage temperature	-20 ... 70 °C
Relative air humidity	5 - 85 % non-condensing
Ambient temperature	0 ... 50 °C
Materials note	Contains PWIS substances
Fieldbus interface	CAN
Fieldbus interface, connection technology	Plug Sub-D 9-pin
Fieldbus interface, transmission rate	1 Mbit/s max. Adjustable
Ethernet, connector plug	RJ45
Ethernet, number	1
Ethernet, data transmission speed	10 Mbit/s
Ethernet, supported protocols	TCP/IP, EasyIP
Programming software	CoDeSys provided by Festo
Programming language	To IEC 61131-3 Ladder diagram (LDR) Statement list (STL) Structured text Function chart Sequential function chart Additional CFC
CPU data	32 bit RISC processor 24 MHz Watchdog