


Manifold subbase VABV-S2-2S-G12-T1

Part number: 560842

FESTO

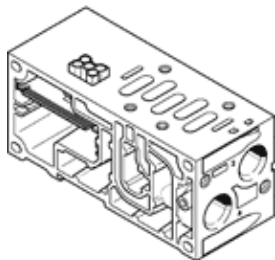

Data sheet

Feature	Value
Grid dimension	59 mm
Valve manifold type	44
Operating pressure MPa	-0.09 ... 1 MPa
Working pressure	-0.9 ... 10 bar
CE symbol (see declaration of conformity)	according to EU low voltage guideline
UKCA marking (see declaration of conformity)	To UK instructions for electrical equipment
Corrosion resistance classification CRC	0 - No corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Product weight	610 g
Pneumatic connection, port 2	G1/2
Pneumatic connection, port 4	G1/2
Materials note	Conforms to RoHS
Material plate	Aluminum die cast