


End plate VMPAL-EPL-SD44

Part number: 560939

FESTO

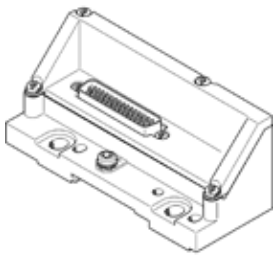

Data sheet

Feature	Value
Width	43 mm
Length	107.3 mm
Max. number of valve positions	32
Valve manifold structure	Valve sizes can be mixed
Max. number of solenoid coils	32
Operating pressure MPa	-0.09 ... 1 MPa
Working pressure	-0.9 ... 10 bar
Pilot pressure MPa	0.3 ... 0.8 MPa
Pilot pressure	3 ... 8 bar
Nominal operating voltage DC	24 V
Corrosion resistance classification CRC	3 - High corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Protection class	IP67
Note on degree of protection	in assembled condition with accessories VMPAL-KM
Ambient temperature	-5 ... 50 °C
Product weight	190 g
Electrical connection 1, function	Multi-pin plug
Electrical connection 1, connection type	Plug
Electrical connection 1, connection technology	Sub-D
Electrical connection 1, number of pins/wires	44
Materials note	Conforms to RoHS
Material end plate	Aluminum die cast PA-reinforced