


End plate VMPAL-EPR

Part number: 560945

FESTO

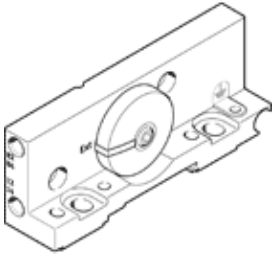

Data sheet

Feature	Value
Width	24.8 mm
Length	107.3 mm
Integrated function	Pilot air selector for choosing the pilot air supply (internal or external)
Valve manifold structure	Valve sizes can be mixed
Operating pressure MPa	-0.09 ... 1 MPa
Working pressure	-0.9 ... 10 bar
Pilot pressure MPa	0.3 ... 0.8 MPa
Pilot pressure	3 ... 8 bar
Corrosion resistance classification CRC	3 - High corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Protection class	IP65 IP67
Note on degree of protection	in assembled condition
Ambient temperature	-5 ... 50 °C
Product weight	180 g
Auxiliary pilot air port 12/14	M7
Pilot exhaust port 82/84	M7
Materials note	Conforms to RoHS
Material end plate	Aluminum die cast PA-reinforced