


Electrical link VMPAL-EVAP-10-2

Part number: 560962

FESTO

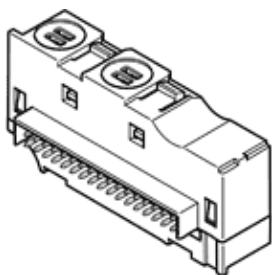

Data sheet

Feature	Value
Valve size	10 mm
Max. number of valve positions	1
Max. number of solenoid coils	2
Integrated function	Colour-coded assignment of the valve function
Nominal operating voltage DC	24 V
Corrosion resistance classification CRC	3 - High corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Ambient temperature	-5 ... 50 °C
Product weight	9 g
Housing color	Black
Material housing	PA
Materials note	Conforms to RoHS