


# Control block CPX-CM-HPP

Part number: 562214

FESTO

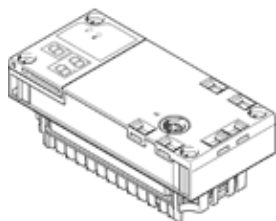

## Data sheet

Feature	Value
Ambient temperature	-5 ... 50 °C
Product weight	140 g
CE symbol (see declaration of conformity)	according to EU low voltage guideline
Protection class	IP65 IP67
Storage temperature	-20 ... 70 °C
Materials note	Conforms to RoHS
PWIS conformity	VDMA24364-B2-L
Power failure buffering	10 ms
Total number of axes	4
Dimensions W x L x H	50 mm x 107 mm x 55 mm
Control interface	CAN-Bus
Fieldbus interface	1x socket, M9, 5-pin
Device-specific diagnostics	Channel and module-oriented diagnostics Undervoltage/short circuit of modules Diagnostics memory
Configuration support	MMI handheld terminal
Parameters configuring	Forcing of channels System parameters
Baud rate	1 Mbit/s
Operating voltage range DC	18 ... 30 V
Nominal operating voltage DC	24 V
Protocol	FHPP
Intrinsic current consumption at operating voltage	Typically 80 mA
Maximum address volume for outputs	32 Byte
Maximum address volume for inputs	32 Byte
Product-specific LED display	Error PL: load supply
Material housing	PA-reinforced PC