

# Blanking plug QSPC10


Part number: 562243

Classic - do not use for new projects

To seal connections on valves or blanking plates.

Modern alternatives can be found by entering the first four characters of the type code in the search field.

FESTO

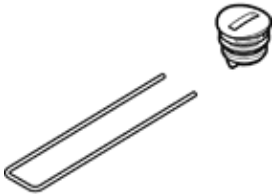

## Data sheet

Feature	Value
Size	Standard
Design	Straight design
Container size	10
Operating pressure for entire temperature range	0 ... 0.8 MPa
Operating pressure complete temperature range	0 ... 8 bar
Operating pressure for entire temperature range	0 ... 116 psi
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7::-]
Corrosion resistance classification CRC	0 - No corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Ambient temperature	-5 ... 60 °C
Product weight	0.4 g
Mounting type	Mounting pin
Pneumatic connection, port 1	Cartridge 10 mm
Materials note	Conforms to RoHS
Material blanking plug	POM
Material o-ring	NBR