


# Connecting cable VMPAL-KM-V-SD44-IP67-

Part number: 562390

FESTO

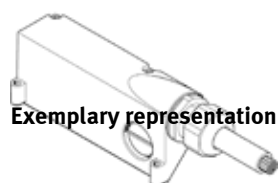

## Data sheet

Feature	Value
Electrical connection	Cable with plug
Cable attribute	Standard
Min. cable bending radius	115 mm
Cable diameter	9.6 mm
Cable structure	36x0,25
Protection class	IP67 to IEC 60529
Ambient temperature with flexible cable installation	-5 ... 80 °C
CE symbol (see declaration of conformity)	in accordance with EU RoHS directive
UKCA marking (see declaration of conformity)	To UK RoHS instructions
PWIS conformity	VDMA24364-B1/B2-L
Materials note	Conforms to RoHS
Corrosion resistance classification CRC	2 - Moderate corrosion stress
Material cable sheath	PVC