


Connecting cable

NEBV-S1W25-K-2.5-N-LE15

Part number: 565280

FESTO

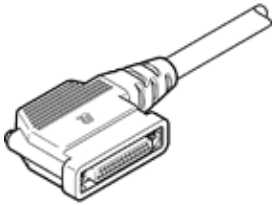

Data sheet

Feature	Value
Assembly position	Any
Cable attribute	For static applications
Operating voltage range DC	≤ 24 V
Acceptable current load at 40°C	2.95 A
Protection class	IP65
Ambient temperature with flexible cable installation	-5 ... 80 °C
Ambient temperature	-40 ... 80 °C
Product weight	500 g
Electrical connection	25-pin Plug socket Sub-D
Cable structure	18 x 0,34 mm ²
Cable diameter	9.5 mm
Cable length	2.5 m
Mounting type	4-40UNC
Materials note	Conforms to RoHS
Materials information, housing	TPE
Materials information, cable sheaths	PVC
Material information for crimp connectors	Bronze Gold plated