


# Connecting cable NEBV-S1W44-K-2.5-N-LE39

Part number: 565286

FESTO

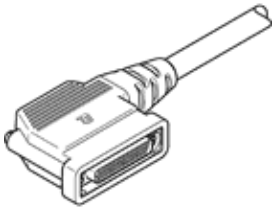

## Data sheet

Feature	Value
Assembly position	Any
Cable attribute	For static applications
Operating voltage range DC	$\leq 24$ V
Acceptable current load at 40°C	0.86 A
Protection class	IP65
Ambient temperature with flexible cable installation	-5 ... 80 °C
Ambient temperature	-40 ... 80 °C
Product weight	490 g
Electrical connection	44-pin Plug socket Sub-D
Cable structure	40 x 0,14 mm <sup>2</sup>
Cable diameter	8.9 mm
Cable length	2.5 m
Mounting type	4-40UNC
Materials note	Conforms to RoHS
Materials information, housing	TPE
Materials information, cable sheaths	PVC
Material information for crimp connectors	Bronze Gold plated