


# Connecting cable NEBV-S1G44-K-2.5-N-LE39

Part number: 565289

FESTO

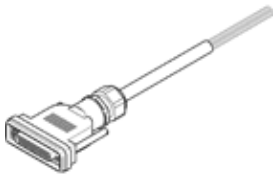

## Data sheet

Feature	Value
Mounting type	4-40UNC
Assembly position	Any
Product weight	389 g
Electrical connection	44-pin Plug socket Sub-D
Operating voltage range DC	$\leq 30$ V
Acceptable current load at 40°C	0.86 A
Cable length	2.5 m
Cable attribute	For static applications
Min. cable bending radius	95 mm
Cable diameter	9.6 mm
Cable diameter tolerance	$\pm 0,5$ mm
Cable structure	40x0,14
Protection class	IP65 IP67 in assembled condition
Ambient temperature	-5 ... 60 °C
CE symbol (see declaration of conformity)	in accordance with EU RoHS directive
UKCA marking (see declaration of conformity)	To UK RoHS instructions
PWIS conformity	VDMA24364-B2-L
Materials note	Conforms to RoHS
Corrosion resistance classification CRC	2 - Moderate corrosion stress
Material cable sheath	PVC
Material housing	PBT
Material electrical contact	Bronze Gold plated