


# Plug NECU-L3G8-C2-IS

Part number: 565709

FESTO

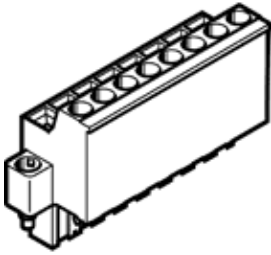

## Data sheet

Feature	Value
Connection frequency	100
Assembly position	Any
Product weight	55.5 g
Electrical connection	8-pin Screwed terminal Plug straight
Operating voltage range DC	0 ... 30 V
Acceptable current load at 40°C	12 A
Surge strength	4 kV
Terminal cross-section	0.2 ... 2.5 mm <sup>2</sup>
Ambient temperature	-40 ... 85 °C
PWIS conformity	VDMA24364-B2-L
Materials note	Conforms to RoHS
Degree of contamination	3
Corrosion resistance classification CRC	2 - Moderate corrosion stress
Material housing	PA
Housing color	blue
Material electrical contact	Copper alloy Galvanized