


# Electrical sub-base VAVE-L1-1VL1-LP

Part number: 566722

FESTO

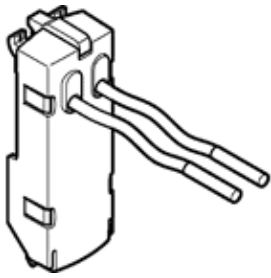

## Data sheet

| Feature                                 | Value                   |
|---|-------------------------|
| Polarity protected                      | Bipolar                 |
| Additional functions                    | Spark arresting         |
| Signal status display                   | LED                     |
| Nominal operating voltage DC            | 24 V<br>12 V            |
| Surge strength                          | 0.8 kV                  |
| Degree of contamination                 | 3                       |
| Extended ambient temperature            | -5 - 60 °C              |
| Corrosion resistance classification CRC | 0 - No corrosion stress |
| PWIS conformity                         | VDMA24364-B1/B2-L       |
| Protection class                        | IP40                    |
| Ambient temperature                     | -5 ... 50 °C            |
| Assembly position                       | Any                     |
| Product weight                          | 4.6 g                   |
| Terminal cross-section                  | 0.14 mm <sup>2</sup>    |
| Electrical connection                   | Stranded wire           |
| Cable length                            | 0.5 m                   |
| Wire ends                               | Wire end ferrule        |
| Protective earth connection             | Not available           |
| Mounting type                           | Clip                    |
| Housing color                           | Black                   |
| Materials note                          | Conforms to RoHS        |
| Material housing                        | PA                      |