


# Electrical sub-base VAVE-L1-1L2-LR

Part number: 566727

FESTO

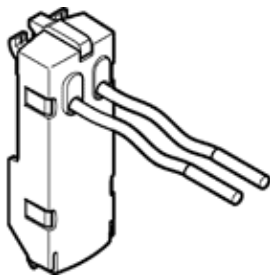

## Data sheet

Feature	Value
Polarity protected	for operating voltage
Additional functions	Spark arresting Reduction of holding current
Signal status display	LED
Nominal operating voltage DC	24 V
Surge strength	0.8 kV
Degree of contamination	3
Authorization	RCM Mark
CE symbol (see declaration of conformity)	according to EU-EMV guideline
UKCA marking (see declaration of conformity)	To UK instructions for EMC
Corrosion resistance classification CRC	0 - No corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Protection class	IP40
Ambient temperature	-5 ... 60 °C
Assembly position	Any
Product weight	7.8 g
Terminal cross-section	0.14 mm <sup>2</sup>
Electrical connection	Stranded wire
Cable length	1 m
Wire ends	Wire end ferrule
Protective earth connection	Not available
Mounting type	Clip
Housing color	Black
Materials note	Conforms to RoHS
Material housing	PA