


AS-i module CESA-GW-AS-PB

Part number: 567032
Product to be discontinued

FESTO

Type to be discontinued. Available until 2021. See Support Portal for alternative products.

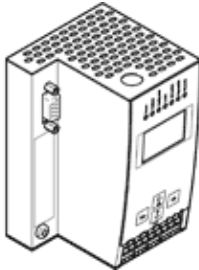

Data sheet

| Feature | Value |
|---|--|
| Dimensions W x L x H | 75 mm x 120 mm x 83 mm |
| Control elements | 4 keys |
| Status displays | LCD display Yellow LED planning mode Green LED AS-i normal operation Green LED AS-i voltage OK Green LED PROFIBUS master Green LED slave programming Green LED voltage ON Red LED configuration error |
| Operating voltage | AS-i voltage 30 V DC |
| Current consumption | 200 mA from the AS-interface circuit |
| Authorization | C-Tick c UL us - Listed (OL) |
| CE symbol (see declaration of conformity) | according to EU-EMV guideline |
| Corrosion resistance classification CRC | 0 - No corrosion stress |
| Storage temperature | -25 ... 85 °C |
| Protection class | IP20 |
| Ambient temperature | 0 ... 55 °C |
| Test for insensitivity to shock | to EN 61131-2 |
| Test for insensitivity to vibration | to EN 61131-2 |
| Product weight | 460 g |
| Fieldbus interface, transmission rate | 9.6 kbit/s up to 12 mbit/s |
| Fieldbus interface, connection technology | Socket Sub-D 9-pin |
| Fieldbus interface | PROFIBUS to DIN 19245 Part 3 |
| Programming/diagnostic interface | Serial interface RS 232 |
| Materials note | Contains PWIS substances Conforms to RoHS |
| Material housing | High alloy steel, non-corrosive |