


Manifold strip

VABM-B6-E-N12-6-M1

Part number: 568182

FESTO

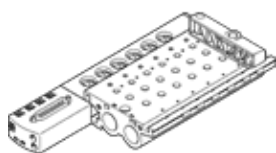

Data sheet

| Feature | Value |
|---|---|
| Grid dimension | 21 mm |
| Max. number of valve positions | 6 |
| Corrosion resistance classification CRC | 2 - Moderate corrosion stress |
| Max. tightening torque, H-rail mounting | 1.5 Nm |
| Max. tightening torque, valve mounting | 2 Nm |
| Max. tightening torque, wall mounting | 5 Nm |
| Product weight | 915 g |
| Auxiliary pilot air port 12/14 | NPT1/8-27 |
| Pneumatic connection, port 1 | NPT1/2-14 |
| Pneumatic connection, port 3 | NPT1/2-14 |
| Materials note | Free of copper and PTFE Conforms to RoHS |
| Material manifold | Wrought Aluminum alloy |