


Push-in sleeve NPQM-D-S14-E-P10

Part number: 570455

FESTO

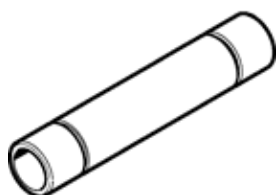

Data sheet

Feature	Value
Size	Standard
Nominal size	12 mm
Design	Straight design
Container size	10
Operating pressure for entire temperature range	-0.095 ... 1.6 MPa
Operating pressure complete temperature range	-0.95 ... 16 bar
Operating pressure for entire temperature range	-13.775 ... 232 psi
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
Note on operating and pilot medium	Lubricated operation possible
Corrosion resistance classification CRC	1 - Low corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Ambient temperature	-20 ... 70 °C
Product weight	18.5 g
Pneumatic connection, port 1	Push-in sleeve diameter 14 mm
Pneumatic connection, port 2	Push-in sleeve QS-14
Materials note	Conforms to RoHS
Material housing	Nickel-plated brass