


Plug FBS-SCRJ-PP-GS

Part number: 571017

FESTO

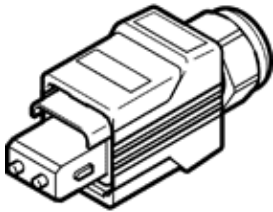

Data sheet

Feature	Value
Product weight	60 g
Note regarding fieldbus interface	PROFINET LWL
Ethernet cable specification	fiber-optic cables Polymer fiber 980/1000µm Individual core diameter: 2.2 mm
Permissible cable diameter	6.5 ... 9.5 mm
Protection class	IP65 IP67 to IEC 60529
Ambient temperature	-40 ... 70 °C
Storage temperature	-40 ... 70 °C
PWIS conformity	VDMA24364-B2-L
Materials note	Conforms to RoHS
Corrosion resistance classification CRC	1 - Low corrosion stress
Material housing	Zinc die-casting Nickel plated
Material seals	NBR TPE