


# Adapter VAVE-C8-1R8

Part number: 571686  
Classic - do not use for new projects

FESTO

Modern alternatives can be found by entering the first four characters of the type code in the search field.

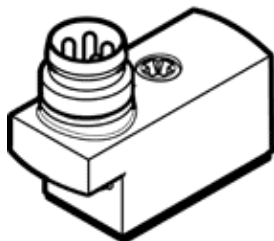

## Data sheet

Feature	Value
Signal status display	LED
Nominal operating voltage DC	24 V
Corrosion resistance classification CRC	2 - Moderate corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Protection class	IP65 to IEC 60529
Ambient temperature	-5 ... 60 °C
Assembly position	Any
Tightening torque	0.25 Nm
Product weight	3.5 g
Electrical connection	3-pin/2-pin M8 / - Plug / socket
Protective earth connection	Not available
Mounting type	On solenoid valve with M2 central screw
Materials note	Conforms to RoHS
Material housing	PA
Material electrical contact	Bronze