


Plastic tubing PAN-MF-6X1-SW-500

Part number: 572093

FESTO

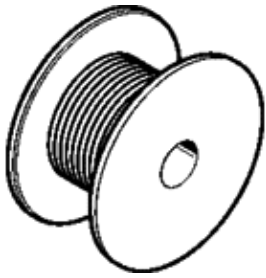

Data sheet

| Feature | Value |
|------------------------------------------|-------------------------------------------------------------------------|
| Outside diameter | 6 mm |
| Bending radius relevant for flow rate | 35 mm |
| Inside diameter | 4 mm |
| Min. bending radius | 15 mm |
| Conforms to standard | DIN 73378-PA12-PHL |
| Tubing characteristics | Suitable for energy chains |
| Temperature-dependent operating pressure | -0.095 ... 2.7 MPa |
| Temperature dependent working pressure | -0.95 ... 27 bar |
| Temperature-dependent operating pressure | -13.775 ... 391.5 psi |
| Operating medium | Compressed air in accordance with ISO8573-1:2010 [7:-:-] Mineral oil |
| PWIS conformity | VDMA24364-B2-L |
| Ambient temperature | -60 ... 100 °C |
| Product weight according to length | 0.016 kg/m |
| Pneumatic connection | For push-in connector outside diameter 6 mm |
| Color | Black |
| Shore hardness | D 65 +/-3 |
| Materials note | Conforms to RoHS |
| Material tubing | Polyamide 12 |