


# Cable socket

## NEFU-X24F-1-M12G4

Part number: 572227  
Product to be discontinued

FESTO

Type to be discontinued. Available until 2023. See Support Portal for alternative products.

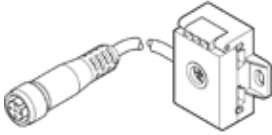

## Data sheet

Feature	Value
Width	36 mm
Height	40 mm
Length	40 mm
Mounting type	with through hole
Product weight	60 g
Fieldbus interface	bush, M12x1, 4-pin, A-coded
DC operating voltage, AS interface	26.5 ... 31.6 V
Nominal DC operating voltage, AS interface	26.5 V
DC operating voltage, load voltage	20.4 ... 26.4 V
Nominal DC operating voltage, load voltage	24 V
Protection class	IP65 in assembled condition to IEC 60529
Ambient temperature	-25 ... 75 °C
Storage temperature	-25 ... 85 °C
PWIS conformity	VDMA24364-B2-L
Materials note	Conforms to RoHS
Material housing	PA
Material cover	PA