


# Plug NECU-S1W9-C2-APB

Part number: 574589

FESTO

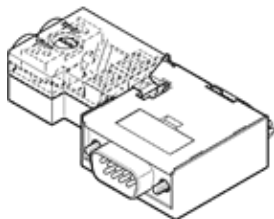

## Data sheet

| Feature                                 | Value                        |
|---|------------------------------|
| Mounting type                           | 4-40 UNC-2B                  |
| Product weight                          | 57.48 g                      |
| Fieldbus interface                      | Sub-D, 9-pin, socket         |
| Electrical connection 1                 | Sub-D plug, 9-pin            |
| Electrical connection 2                 | IDC terminal                 |
| Baud rate                               | 12 Mbit/s                    |
| Permissible cable diameter              | 8 mm<br>8 mm                 |
| Terminal cross-section                  | 0.08 ... 0.5 mm <sup>2</sup> |
| Protection class                        | IP20                         |
| Ambient temperature                     | -20 ... 70 °C                |
| Relative air humidity                   | 75% at 25°C                  |
| PWIS conformity                         | VDMA24364-B2-L               |
| Materials note                          | Conforms to RoHS             |
| Corrosion resistance classification CRC | 1 - Low corrosion stress     |
| Material housing                        | Reinforced PC                |