 



# vertical pressure exhaust plate

## VABF-L1-P7A13-G18

Part number: 574595

FESTO

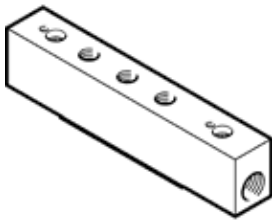

### Data sheet

Feature	Value
Grid dimension	16 mm
Max. number of valve positions	1
Operating pressure MPa	-0.09 ... 1 MPa
Working pressure	-0.9 ... 10 bar
Authorization	RCM Mark c UL us - Recognized (OL)
Corrosion resistance classification CRC	2 - Moderate corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Max. tightening torque, valve mounting	0.65 Nm
Product weight	350 g
Pneumatic connection, port 3	G1/8
Pneumatic connection, port 5	G1/8
Materials note	Conforms to RoHS
Material plate	Wrought Aluminum alloy