


Distributor block

FR-8-1/2

Part number: 6411

FESTO

For distribution of compressed air.

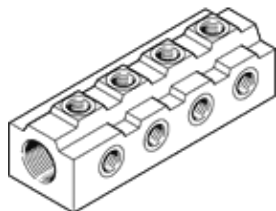

Data sheet

Feature	Value
Nominal size	18.6 mm
Assembly position	Any
Operating pressure complete temperature range	0 ... 16 bar
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
Note on operating and pilot medium	Lubricated operation possible (subsequently required for further operation)
Corrosion resistance classification CRC	0 - No corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Ambient temperature	-10 ... 60 °C
Nominal tightening torque	35 Nm
Tolerance for nominal tightening torque	± 10 %
Product weight	1,000 g
Number of outputs	8
Number of supply lines	1
Pneumatic connection, port 1	Female thread G3/4
Pneumatic connection, port 2	Female thread G1/2
Materials note	Conforms to RoHS
Material housing	Aluminum die cast