 



AND gate ZK-1/8-B

Part number: 6680

FESTO

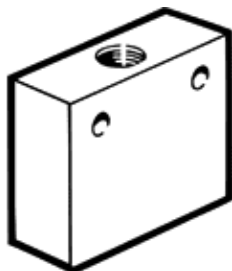

Data sheet

| Feature | Value |
|------------------------------------|---|
| Valve function | AND function |
| Pneumatic connection, port 1 | G1/8 |
| Pneumatic connection, port 2 | G1/8 |
| Mounting type | with through hole |
| Standard nominal flow rate | 550 l/min |
| Working pressure | 1 ... 10 bar |
| Ambient temperature | -10 ... 60 °C |
| Material housing | Wrought Aluminum alloy Anodized |
| Operating medium | Compressed air in accordance with ISO8573-1:2010 [7:-:-] |
| Nominal size | 4.5 mm |
| Assembly position | Any |
| Note on operating and pilot medium | Lubricated operation possible (subsequently required for further operation) |
| PWIS conformity | VDMA24364-B1/B2-L |
| Medium temperature | -10 ... 60 °C |
| Product weight | 45 g |
| Pneumatic connection, port 3 | G1/8 |
| Materials note | Conforms to RoHS |
| Material seals | NBR |