 



# OR gate OS-PK-3

Part number: 6684

FESTO

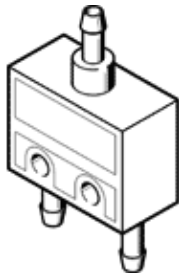

## Data sheet

Feature	Value
Valve function	OR function
Pneumatic connection, port 1	PK-3
Pneumatic connection, port 2	PK-3
Mounting type	with through hole
Standard nominal flow rate	120 l/min
Working pressure	1.6 ... 8 bar
Ambient temperature	-10 ... 60 °C
Material housing	POM
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:::]
Nominal size	2.4 mm
Assembly position	Any
Note on operating and pilot medium	Lubricated operation possible (subsequently required for further operation)
PWIS conformity	VDMA24364-B1/B2-L
Medium temperature	-10 ... 60 °C
Product weight	9 g
Pneumatic connection, port 3	PK-3
Materials note	Conforms to RoHS
Material seals	NBR