 



# AND gate ZK-PK-3

Part number: 6685

FESTO

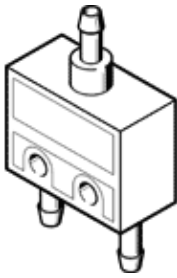

## Data sheet

| Feature                            | Value   |
|------------------------------------|---|
| Valve function                     | AND function  |
| Pneumatic connection, port 1       | PK-3  |
| Pneumatic connection, port 2       | PK-3  |
| Mounting type                      | with through hole   |
| Standard nominal flow rate         | 120 l/min   |
| Working pressure                   | 1.6 ... 8 bar   |
| Ambient temperature                | -10 ... 60 °C   |
| Material housing                   | Brass<br>POM  |
| Operating medium                   | Compressed air in accordance with ISO8573-1:2010 [7:-:-]                    |
| Nominal size                       | 2.4 mm  |
| Assembly position                  | Any   |
| Note on operating and pilot medium | Lubricated operation possible (subsequently required for further operation) |
| PWIS conformity                    | VDMA24364-B1/B2-L   |
| Medium temperature                 | -10 ... 60 °C   |
| Product weight                     | 10 g  |
| Pneumatic connection, port 3       | PK-3  |
| Materials note                     | Conforms to RoHS  |
| Material seals                     | NBR   |