


# Plastic tubing PCN-4-NT

Part number: 7134  
Product to be discontinued

FESTO

Low pressure PVC tubing for use with condensate drains on D-series service units.

Type to be discontinued. Available until 2018. See Support Portal for alternative products.

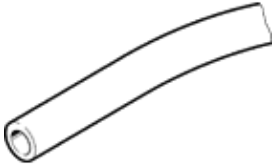

## Data sheet

Feature	Value
Outside diameter	6.5 mm
Inside diameter	4 mm
Operating pressure complete temperature range	-0.5 ... 0.25 bar
Ambient temperature	-10 ... 60 °C
Product weight according to length	0.025 kg/m
Color	neutral
Shore hardness	76
Materials note	Conforms to RoHS
Materials information for tubing	PVC