


Multi-socket KDVF-16-B

Part number: 7564

FESTO

For multi-tube connection of plastic tubing with 2, 3 and 4 mm ID.

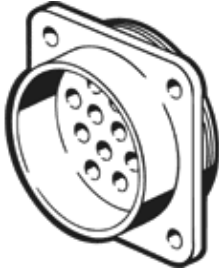

Data sheet

Feature	Value
Nominal size	4 mm
Working pressure	-0.95 ... 16 bar
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
Note on operating and pilot medium	Lubricated operation possible (subsequently required for further operation)
Corrosion resistance classification CRC	2 - Moderate corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Medium temperature	-10 ... 60 °C
Ambient temperature	-10 ... 60 °C
Product weight	64 g
Max. number of connections	16
Pneumatic connection	PK-2 PK-3 PK-4
Color	Grey
Materials note	Conforms to RoHS