


# Air cushion plate ATBT-...-

Part number: 8021855

FESTO

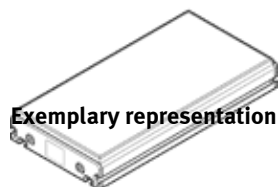

## Data sheet

Overall data sheet – Individual values depend upon your configuration.

Feature	Value
Size	100
Bearing length	100 ... 1,500 mm
Assembly position	Horizontal
Mounting type	With slot nuts
Pneumatic connection	G1/4
Working pressure	≤ 2 bar
Operating medium	Compressed air to ISO 8573-1:2010 [1:4:1]
Note on operating and pilot medium	Lubricated operation not possible
Ambient temperature	10 ... 50 °C
Medium temperature	10 ... 50 °C
Corrosion resistance classification CRC	2
Product weight according to length	3.6 kg/m
Shore hardness	D 80 +/- 5
Materials note	Conforms to RoHS
Max. surface load during operation	400 kg/m <sup>2</sup>
Repetition accuracy of the flying height	±10 µm
Flatness, adjusted	60 µm
Flatness, mounted	110 µm