


# Flow control

## VFFG-T-M5-15

Part number: 8025715

FESTO

This type is suitable for vacuum.

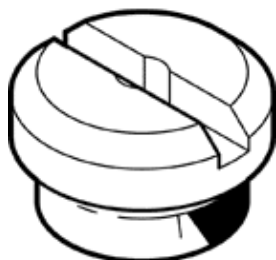

### Data sheet

Feature	Value
Valve function	Throttle function
Mounting type	with thread
Standard nominal flow rate in flow control direction	67.4 l/min
Working pressure	-0.9 ... 10 bar
Ambient temperature	-5 ... 60 °C
Nominal size	1.55 mm
b value	0.5
C value	0.25 l/sbar
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:4:4]
Note on operating and pilot medium	Lubricated operation possible (subsequently required for further operation)
PWIS conformity	VDMA24364-B1/B2-L
Storage temperature	-20 ... 60 °C
Product weight	0.5 g
Materials note	Conforms to RoHS
Material hollow bolt	PA