


Supply plate

VABF-B10-30-P1A4-G38

Part number: 8026434

FESTO

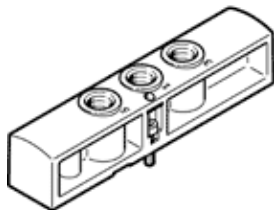

Data sheet

Feature	Value
Operating pressure MPa	-0.09 ... 1 MPa
Working pressure	-0.9 ... 10 bar
Corrosion resistance classification CRC	2 - Moderate corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Max. tightening torque	6 Nm
Product weight	167 g
Mounting type	with through hole
Pneumatic connection, port 1	G3/8
Pneumatic connection, port 3	G3/8
Pneumatic connection, port 5	G3/8
Materials note	Conforms to RoHS
Material supply plate	Aluminum die cast