


Linear gantry EXCT-100- -

Part number: 8026577

FESTO

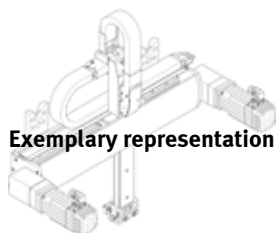

Exemplary representation

Data sheet

Overall data sheet – Individual values depend upon your configuration.

Feature	Value
Size	100
Assembly position	Vertical
Design structure	Linear gantry
Working pressure	-0.95 ... 8 bar
Max. acceleration	30 m/s ²
Max. speed	4 m/s
Repetition accuracy	±0,1 mm
Duty cycle	100 %
PWIS conformity	VDMA24364 zone III
Storage temperature	-10 ... 60 °C
Relative air humidity	0 - 90 %
Sound pressure level	77 dB(A)
Protection class	IP40
Ambient temperature	10 ... 40 °C
Max. process force in Z direction	500 N
Rated load with maximum dynamic response	10 kg
Mounting type	With mounting kit With slot nuts
Materials note	Conforms to RoHS