


# Elbow fitting NPFC-L-2M5-M

Part number: 8030222

FESTO

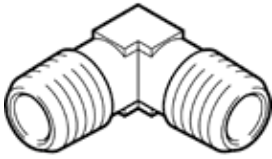

## Data sheet

| Feature                                 | Value  |
|---|--|
| Material threaded fitting               | Nickel-plated brass  |
| Container size                          | 10   |
| Working pressure                        | -0.95 ... 50 bar   |
| Operating medium                        | Compressed air in accordance with ISO8573-1:2010 [-:--:--] |
| Corrosion resistance classification CRC | 1 - Low corrosion stress                                   |
| PWIS conformity                         | VDMA24364-B1/B2-L  |
| Ambient temperature                     | -20 ... 150 °C   |
| Product weight                          | 7.7 g  |
| Pneumatic connection, port 1            | M5   |
| Pneumatic connection, port 2            | M5   |
| Materials note                          | Conforms to RoHS   |