


Y-fitting NPFC-Y-R18-2G18-MFF

Part number: 8030231

FESTO

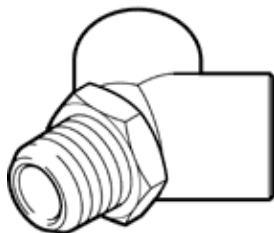

Data sheet

| Feature | Value |
|---|--|
| Material threaded fitting | Nickel-plated brass |
| Container size | 10 |
| Working pressure | -0.95 ... 50 bar |
| Operating medium | Compressed air in accordance with ISO8573-1:2010 [-:--:--] |
| Corrosion resistance classification CRC | 1 - Low corrosion stress |
| PWIS conformity | VDMA24364-B1/B2-L |
| Ambient temperature | -20 ... 150 °C |
| Product weight | 30.7 g |
| Pneumatic connection, port 1 | R1/8 |
| Pneumatic connection, port 2 | G1/8 |
| Materials note | Conforms to RoHS |