


**T fitting**  
**NPFC-T-G12-2R12-FMM**  
Part number: 8030258

**FESTO**

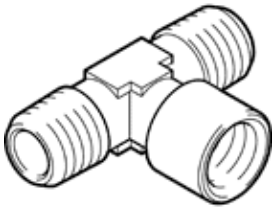

**Data sheet**

<b>Feature</b>	<b>Value</b>
Material threaded fitting	Nickel-plated brass
Container size	10
Working pressure	-0.95 ... 50 bar
Operating medium	Compressed air in accordance with ISO8573-1:2010 [-:--:]
Corrosion resistance classification CRC	1 - Low corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Ambient temperature	-20 ... 150 °C
Product weight	100.7 g
Pneumatic connection, port 1	G1/2
Pneumatic connection, port 2	R1/2
Materials note	Conforms to RoHS