


# Subbase VMPA1-FB-AP-4-1-S1-RV

Part number: 8034551

FESTO

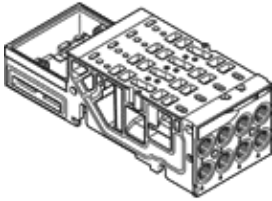

## Data sheet

Feature	Value
Width	50 mm
Length	107.3 mm
Grid dimension	10.5 mm
Max. number of valve positions	4
Operating pressure MPa	-0.09 ... 1 MPa
Working pressure	-0.9 ... 10 bar
Pilot pressure MPa	0.3 ... 0.8 MPa
Pilot pressure	3 ... 8 bar
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:4:4]
Corrosion resistance classification CRC	0 - No corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Ambient temperature	-5 ... 50 °C
Product weight	190 g
Materials note	Conforms to RoHS
Material of connecting plate	Aluminum die cast